

## Power Cords

Commercial/Residential  
For Portable Generators



30 Amp




30 Amp






50 Amp

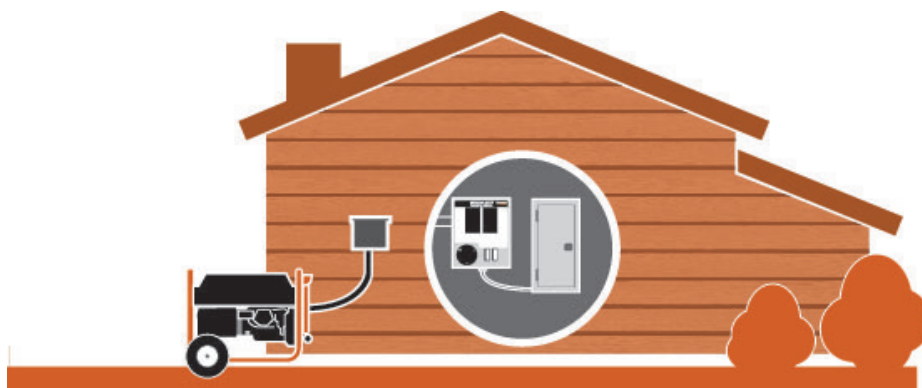

- Power cords are the connecting link between your generator and transfer switch or power inlet box, power tool, or appliance.
- 30 amp and 50 amp cords available in multiple lengths.



# Power Cords

## Specifications

Model	6112	6327	6328	6329	6387	6388
UPC	696471061123	696471063271	696471063288	696471063295	696471063875	696471063882
Length ft. (m)	20 (6)	10 (3)	25 (7.6)	50 (15)	75 (22.5)	100 (30)
Amperage	30					
Voltage Rating	120/240 VAC			125/250 VAC		
Max Generator Size (Watts)	7500					
NEMA Configuration	Plug  L14-30	Connector  (4) 5-20	Plug and Connector  L14-30			
Cord Type (Gauge/Wire)	10/4					
Cord Material	Thermoset Weather Resistant Compound		Thermoplastic Weather Resistant Compound	Thermoset Weather Resistant Compound		
Compatible Generac Generators	For use with generators equipped with 30 Amp outlets including: XG4000, XP4000, GP5500, GP6500E, GP7500E, XG6500, XG7000E, XG8000E, XP6500E, XP8000E					
Compatible Generac GenTran Transfer Switches (Model #s)	-		6376, 6378, 6379, 6382, 6294, 6408, 6295			
Compatible Generac GenTran Power Inlet Boxes (Model #s)	-		6337, 6340, 6343, 6346			
Warranty	-		2 Years			

Model	6330	6389	6390	6391	6392
UPC	696471063301	696471063899	696471063905	696471063912	696471063929
Length ft. (m)	10 (3)	25 (7.6)	50 (15)	75 (22.5)	100 (30)
Amperage	50				
Voltage Rating	125/250 VAC				
Max Generator Size (Watts)	12500				
NEMA Configuration	Plug  14-50		Connector  CS6364		
Cord Type (Gauge/Wire)	6/4				
Cord Material	Thermoset Weather Resistant Compound				
Compatible Generac Generators	For use with generators equipped with 50 Amp outlets including: GP15000E, GP17500E, XG10000E, XP10000E				
Compatible Generac GenTran Transfer Switches (Model #s)	6294, 6295, 6376, 6377, 6378, 6379, 6382, 6408				
Compatible Generac GenTran Power Inlet Boxes (Model #s)	6338, 6341, 6344, 6347				
Warranty	2 Years				

## Dimensions and Weights

Model	6327	6328	6329	6387	6388	6112	6330	6389	6390	6391	6392
Product L x W x H in (mm)	11 x 10 x 3 (279 x 254 x 76)	16 x 15 x 3.5 (406 x 381 x 89)	16 x 15 x 3.5 (406 x 381 x 89)	22 x 22 x 5 (559 x 559 x 127)	22 x 22 x 5 (559 x 559 x 127)	10 x 10 x 3 (254 x 254 x 76)	16 x 15 x 3.5 (406 x 381 x 89)	16 x 15 x 3.5 (406 x 381 x 89)	22 x 22 x 5 (559 x 559 x 127)	22 x 22 x 5 (559 x 559 x 127)	22 x 22 x 5 (559 x 559 x 127)
Product Weight lbs (kg)	7 (3)	11 (5)	18 (8)	25 (11)	32 (14.5)	7.5 (3.5)	8 (3.5)	8 (3.5)	32 (14.5)	50 (23)	85 (39)
Master Carton Quantity	3	3	-	-	-	2	3	3	-	-	-
Master Carton UPC	20696471063275	20696471063282	-	-	-	20696471061127	20696471063305	20696471063893	-	-	-
Master Carton L x W x H in (mm)	11 x 10 x 10 (300 x 254 x 254)	17 x 16 x 13 (432 x 406 x 330)	-	-	-	7.75 x 11.75 x 11 (197 x 298 x 282)	17 x 16 x 13 (432 x 406 x 330)	17 x 16 x 13 (432 x 406 x 330)	-	-	-
Master Carton Weight lbs (kg)	35 (16)	33 (15)	-	-	-	15.5 (7)	40 (18)	51 (23)	-	-	-

# GENERAC®

Generac Power Systems, Inc. • P.O. Box 8, Waukesha, WI 53187 • generac.com

©2013 Generac Power Systems, Inc. All rights reserved. All specifications are subject to change without notice. Bulletin 0196850-A / Printed in U.S.A. 09/13/13